

## AIR COMPRESSORS



Description	System Capacity	Part Number	Short Code	List Price
<b>GAST AIR COMPRESSORS - BARE</b>				
1/6 HP, 115-60-1, 1LAA-10-M100X	90 Gallons	6999990904	16A	\$S\$1,875.98
1/4 HP, 115-60-1, 2LAF-10-M200X	150 Gallons	6999991538	14A	\$S\$2,239.46
1/3 HP, 115-60-1, 3LBA-33-M300X	180 Gallons	6702000033	13A	\$S\$2,708.48
1/2 HP, 115-60-1, 4LCB-10-M450X	300 Gallons	6999991518	12A	\$S\$3,318.19
3/4 HP, 115/208-230-60-1, 5LCA-23-550NGX	400 Gallons	6702000075	34A	\$S\$3,451.08
1 HP, 115/230-60-1, 6LCF-10-M616NEX	600 Gallons	6999991315	1A	\$S\$4,447.81
1.5 HP, 115/230-60-1, 7LDE-10-M700X	800 Gallons	6702000150	112A	\$S\$7,465.14
2 HP, 115/230-60-1, 8LDF-10-M850X	1000 Gallons	6999991569	2A	\$S\$9,184.85

\*Above models can be outfitted with accessories of your own such as pressure switch, check valve, air tank and can also be used with a Model B Pressure Maintenance Device to set supervisory pressure settings. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power



Description	System Capacity	Part Number	Short Code	List Price
<b>GAST ROCKING PISTON AIR COMPRESSORS WITH SURGE TANK, CHECK VALVE AND DIGITAL PRESSURE SWITCH</b>				
87R-100S, 1/2 HP, 120V, 60HZ	See below	6990026704	G87R100S	\$S\$ 5,918.51

\*Above model features a digital pressure switch with adjustable pressure settings from 10 PSI up to 50 PSI and with a 5 PSI differential. Ultra quiet compressor and fast install Unistrut rail design for mounting to a riser. All mounting hardware and airline hose connector included. Use adjustable pressure settings for system pressure, or with a Model A Pressure Maintenance Device to set supervisory pressure settings. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power. System Capacity (gallons) ratings: 10 PSI Cut-out = 1,350 Gallons; 18 PSI Cut-out = 725 Gallons; 40 PSI Cut-out = 300 Gallons. Consult factory for more capacity rating if needed

Description	System Capacity	Part Number	Short Code	List Price
<b>UL LISTED - GAST AIR COMPRESSORS WITH CHECK VALVE AND PRESSURE SWITCH</b>				
1/6 HP, UL 115-60-1, 1LAA-46S-M100GX	90 Gallons	6999995064	16PAU	\$S\$ 3,013.34
1/4 HP, UL 115-60-1, 2LAF-46S-M200EX	150 Gallons	6999995080	14PAU	\$S\$ 3,447.17
1/3 HP, UL 115-60-1, 3LBA-46S-M300AX	180 Gallons	6999995134	13PAU	\$S\$ 3,630.87
1/2 HP, UL 115-60-1, 4LCB-46S-M450GX	300 Gallons	6999995098	12PAU	\$S\$ 4,369.65
3/4 HP, UL 115/208-230-60-1, 5LCA-46S-M550GX	400 Gallons	6999995066	34PAU	\$S\$ 4,807.39
1 HP, UL 115/230-60-1, 6LCF-46S-M616NEX	600 Gallons	6999994852	1PAU	\$S\$ 5,745.42
1.5 HP, UL 115/230-60-1, 7LDE-46S-M750X	800 Gallons	6999995067	112PAU	\$S\$ 8,512.60
2 HP, UL 115/230-60-1, 8LDF-46S-M850X	1000 Gallons	6990008225	2PAU	\$S\$10,857.67

\*Above models can be mounted to a riser using a Gast mounting bracket. Pressure switch is factory set with 40 PSI cut-in and 50 PSI cut-out pressure setting. Cut-in pressure cannot be adjusted below 30 PSI. On/Off differential of 10 PSI cannot be changed (example: if cut-in pressure is lowered to 30 PSI, then the cut-out pressure will be 40 PSI and cannot be changed) These compressors are rated for 50 PSI max pressure. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power



Description	System Capacity	Part Number	Short Code	List Price
<b>NON UL-LISTED GAST AIR COMPRESSORS WITH CHECK VALVE AND PRESSURE SWITCH</b>				
1/6 HP, 115-60-1, 1LAA-32-M100X	90 Gallons	6999991173	16PA	\$S\$ 2,966.43
1/4 HP, 115-60-1, 2LAF-12-M200X	150 Gallons	6999990905	14PA	\$S\$ 3,099.32
1/3 HP, 115-60-1, 3LBA-32-M300X	180 Gallons	6999990906	13PA	\$S\$ 3,427.63
1/2 HP, 115-60-1, 4LCB-21-M450X	300 Gallons	6999990907	12PA	\$S\$ 4,103.87
3/4 HP, 115/230-60-1, 5LCA-22-M550X	400 Gallons	6999990908	34PA	\$S\$ 4,447.81
1 HP, 115/230-60-1, 6LCF-13-M616X	600 Gallons	6999990909	1PA	\$S\$ 5,276.41
1.5 HP, 115/230-60-1, 7LDE-16-M750X	800 Gallons	6999990910	112PA	\$S\$ 8,090.49
2 HP, 115/230-60-1, 8LDF-16-M850X	1000 Gallons	6999991325	2PA	\$S\$10,435.56

\*Above models can be mounted to a riser using a Gast mounting bracket. Pressure switch is factory set with 40 PSI cut-in and 50 PSI cut-out pressure setting. Cut-in pressure cannot be adjusted below 30 PSI. On/Off differential of 10 PSI cannot be changed (example: if cut-in pressure is lowered to 30 PSI, then the cut-out pressure will be 40 PSI and cannot be changed) These compressors are rated for 50 PSI max pressure. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.

## AIR COMPRESSORS



Description	System Capacity	Part Number	Short Code	List Price
<b>NON UL-LISTED GAST AIR COMPRESSORS - TANK MOUNTED AND 100 PSI</b>				
1/6 HP, 115-60-1, 1HAB-11T-M100X, 2 GAL	80 Gallons	6999991027	16TA	S\$ 4,338.38
1/3 HP, 115-60-1, 3HBB-13T-M300AX, 2 GAL	160 Gallons			S\$ Call
3/4 HP, 115/230-60, 55HCD-11T-M550NGX, 20 GAL	340 Gallons	6990012005		S\$10,265.54
1.5 HP, 230-60-1, 7HDD-11TA-M750X, 30 GAL	660 Gallons	6990013330		S\$20,128.51

\*Above models have stored air pressure at 100 PSI. Cut-in pressure of 80 PSI (70 PSI on the 1HAB only) Cut-out pressure of 100 PSI. Use with a Model A Pressure Maintenance Device for supervisory pressure settings. Compressor will cycle less and last longer than compressors with lower max pressure ratings. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power (if no number shown after 60Hz it is 1-phase power)

Description	System Capacity	Part Number	Short Code	List Price
<b>NON UL-LISTED GAST AIR COMPRESSORS - TANK MOUNTED AND 50 PSI</b>				
1/4 HP, 115-60-1, 2LAF-11T-M200X 12 GAL	150 Gallons	6999991163	14TA	S\$ 6,011.19
1/3 HP, 115-60-1, 3LBA-11T-M300AX 12 GAL	180 Gallons	6999991285	13TA	S\$ 6,792.88
1/2 HP, 115-60-1, 4LCB-11T-M450X 20 GAL	300 Gallons	6999991136	12TA	S\$ 7,465.14
3/4 HP, 115/230-60 5LCA-11T-M550X 20 GAL	400 Gallons	6999991217	34TA	S\$ 7,652.74
1 HP, 115/230-60-1,6LCF-11T-M616X 30 GAL	600 Gallons	6999991289	1TA	S\$ 9,341.19
1.5 HP, 115/230-60,7LDE-11T-M750X,30 GAL	800 Gallons	6999991567	112TA	S\$13,874.99
2 HP, 115/230-60-1,8LDF-11TA-M850X,30GAL	1000 Gallons	6999991541	2TA	S\$18,799.64

\*Above models have stored air pressure at 50 PSI. Cut-in pressure of 30 PSI and cut-out pressure of 50 PSI. Use with a Model A Pressure Maintenance Device for supervisory pressure settings if needed. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power (if no number shown after 60Hz it is 1-phase power)

Description	System Capacity	Part Number	Short Code	List Price
<b>UL-LISTED GAST AIR COMPRESSORS - TANK MOUNTED AND 50 PSI</b>				
1/6HP, UL 115-60-1, 1LAA-46T-M100GX, 2GAL	90 Gallons	6999995091	16TAU	S\$ 4,682.32
1/4HP, UL 115-60-1, 2LAF-46T-M200EX, 12GAL	150 Gallons	6999995111	14TAU	S\$ 6,558.38
1/3HP, UL 115-60-1, 3LBA-46T-M300AX, 12GAL	180 Gallons	6999993433	13TAU	S\$ 7,152.46
1/2HP, UL 115-60-1, 4LCB-46T-M450GX, 20GAL	300 Gallons	6999995114	12TAU	S\$ 8,012.32
3/4HP, 115/230-60-1, 5LCA-46T-M550GX, 20GAL	400 Gallons	6999995110	34TAU	S\$ 8,668.94
1HP, 115/230-60-1, 6LCF-46T-M616NEX, 30GAL	600 Gallons	6999995136	1TAU	S\$ 9,653.87
1.5HP, 115/230-60-1, 7LDE-46T-M750X, 30GAL	800 Gallons	6999995056	112TAU	S\$14,375.27
2 HP, 115/230-60-1, 8LDF-46T-M850X, 30GAL	1000 Gallons	6990011326	2TAU	S\$19,299.92

\*Above models are UL Listed air tank compressors and have stored air pressure at 50 PSI. Cut-in pressure of 30 PSI and cut-out pressure of 50 PSI. Use with a Model A Pressure Maintenance Device for supervisory pressure settings if needed. Voltage and power example above: 115-60-1 = 115 volts 60Hz 1-phase power

Description	Part Number	Short Code	List Price
<b>GAST AIR COMPRESSOR - REPAIR KITS*</b>			
K1002 FLOOR MOUNT KIT (87R)	6990026509	K1022	S\$ 120.83
K263 REPAIR KIT, 3/4HP	6888000020	K263	S\$ 617.46
K303 REPAIR KIT 1-1/2HP	6888000030	K303	S\$ 992.67
AT670 MOUNTING BRACKETS, 1/6-1 HP	6999990969	GMB	S\$ 261.79
AT670A, MOUNTING BRACKET, 1.5-2 HP	6990007698	GMBL	S\$ 562.74
SSP-87R6-01 SOUND SHIELD KIT	6990026510	SSP87R6	S\$ 695.70

\*Repair Kit Contains: Gaskets, Piston, Seals, Piston Rings, In/Out Valve Plates, Manifold Seals and Felts (for Filters). SSP-87R6-01 Sound Shield kit provides a retrofit kit of part for Gast 87R-110S compressor shown above and reduces sound levels up to 20%

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.



## AIR COMPRESSORS

Description	System Capacity	Part Number	Short Code	List Price
<b>HEAVY DUTY - SINGLE PHASE - TANK MOUNTED</b>				
S175-HD1-115 (115V, 1HP, 3 GALLON)	175 gallons	6990012386	C175	S\$ 4,992.61
S265H-HD1-115 (115V, 1-1/2 HP, 3 GALLON)	265 gallons	6990012600	C265	S\$ 5,084.75
S325H-HD1-115 (115V, 1-1/2 HP, 3 GALLON)	325 gallons	6990012601	C325	S\$ 5,215.49
S500H-HD1-115 (115V, 1-1/2 HP, 30 GALLON)	500 gallons	6990012602	C500	S\$ 7,873.25
S750H-HD1-230 (3HP,230V,30 GALLON H)	750 gallons	6990013997	C750	S\$ 8,987.86
S900H-HD1-230 (5HP,230V,30 GALLON H)	900 gallons	6990013998	C900	S\$ 9,191.56
S1300H-HD1-230S (5HP,230V,60 GALLON H)	1300 gallons	6990013999	C1300	S\$ 15,531.35
S1700H-HD1-230S (7.5HP,230V,60 GALLON H)	1700 gallons	6990014000	C1700	S\$ 16,423.96
<b>STANDARD DUTY - SINGLE PHASE - TANK MOUNTED</b>				
S300H-SD1-115 (1HP,115V,3 GALLON H)	300 gallons	6990013994	C300	S\$ 4,243.72
S2000H-SD1-230S (7.5HP,230V,60 GALLON H)	2000 gallons			S\$ Call
<b>RISER MOUNTED</b>				
C-AIRE,#S280R-LD1-115P		7M99004812	C280R	S\$ 3,636.52
C-AIRE,#S281R-LD1-115PD		7M99004813	C281R	S\$ 4,543.85
USE PN 6990026563		7M99004814	C30SSOLD	S\$ 278.61

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.




**QRM RISER &  
 TANK MOUNTED  
 AIR  
 COMPRESSORS**

- See Bulletin 256

**NEW**


Description	Part Number	Short Code	List Price
<b>QRM2 AIR COMPRESSORS -- TANKLESS W/CHECK VALVE &amp; PRESSURE SWITCH</b>			
RASCO AIR, QRM25115 1/4HP, 115, TANKLESS	6872000001	14QRM	\$3,931.37
RASCO AIR, QRM2-25220 1/4HP, 220, TANKLESS	6872000002	14QRM220	\$4,337.74
RASCO AIR, QRM2-50115 1/2HP, 115, TANKLESS	6872000005	12QRM	\$5,430.84
RASCO AIR, QRM2-50220 1/2HP, 220, TANKLESS	6872000006	12QRM220	\$5,665.53
RASCO AIR, QRM2-25220-50HZ, 1/4, 220, TNKLSS	6872000011	14QRM50	\$4,337.74
RASCO AIR, QRM2-50220-50HZ, 1/2, 220, TNKLSS	6872000013	12QRM50	\$5,665.53
RASCO AIR, QRM2-25115-4050 1/4HP, 115, TL	6872000040	14QRM4050	\$4,002.25
RASCO AIR, QRM2-50115-4050 1/2HP, 115, TL	6872000042	12QRM4050	\$5,430.84
RASCO AIR, QRM2-25220-4050 1/4HP, 220, TL	6872000041	14QRM2204050	\$4,337.74
RASCO AIR, QRM2-50220-4050 1/2HP, 220, TL	6872000043	12QRM2204050	\$5,665.53
<b>QRM2 AIR COMPRESSORS - TANK MOUNTED</b>			
RASCO AIR, QRM2-25115T 1/4HP, 115, TANK	6872000003	14QRMT	\$4,937.84
RASCO AIR, QRM2-25220T 1/4HP, 220, TANK	6872000004	14QRM220T	\$5,382.01
RASCO AIR, QRM2-50115T 1/2HP, 115, TANK	6872000007	12QRMT	\$6,278.23
RASCO AIR, QRM2-50220T 1/2HP, 220, TANK	6872000008	12QRM220T	\$6,545.99
RASCO AIR, QRM2-100115T, 1 HP, 115, TANK	6872000009	1QRMT	\$8,306.92
RASCO AIR, QRM2-100220T, 1 HP, 220, TANK	6872000010	1QRM220T	\$8,823.54
RASCO AIR, QRM2-25220T-50HZ, 1/4, 220, TANK	6872000012	14QRM50T	\$5,382.01
RASCO AIR, QRM2-50220T-50HZ, 1/2, 220, TANK	6872000014	12QRM50T	\$6,545.99
RASCO AIR, QRM2-100220T-50HZ, 1, 220, TANK	6872000015	1QRM50T	\$8,823.54
<b>CONNECTION KITS</b>			
Connection Kit, Tankless Compressor	650120011G	CKTL	\$ 773.36
Connection Kit, Tank Mounted Compressor	650120011H	CKTM	\$1,863.31
<b>FLEX HOSE -- SOLD SEPARATELY</b>			
Flex Hose, Stainless Steel, 1/2" x 30"	6872000000	QRMFLEX	\$ 286.66

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.

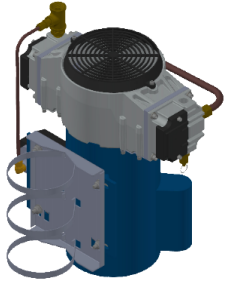

**RRM RISER MOUNTED AIR COMPRESSOR**

• See Bulletin 258

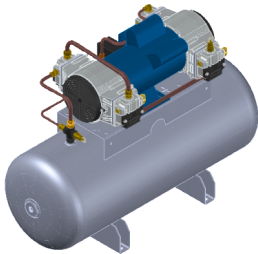

**RTM TANK MOUNTED AIR COMPRESSOR**

• See Bulletin 258

Description	Part Number	Short Code	List Price
<b>RRM AIR COMPRESSORS - TANKLESS W/CHECK VALVE &amp; PRESSURE SWITCH</b>			
RASCO AIR,RRM23016-2026,1/6HP,115/220VAC	6872000020	16RRM	S\$ 3,915.62
RASCO AIR,RRM40033-2026,1/3HP,115/220VAC	6872000021	13RRM	S\$ 4,770.89
RASCO AIR,RRM70050-2026,1/2HP,115/220VAC	6872000022	12RRM	S\$ 6,240.43
RASCO AIR,RRM23016-4050 1/6HP,115,CP	6872000044	16RRM4050	S\$ 3,914.05
RASCO AIR,RRM40033-4050 1/3HP,115,CP	6872000045	13RRM4050	S\$ 4,764.59
RASCO AIR,RRM70050-4050 1/2HP,115,CP	6872000046	12RRM4050	S\$ 6,221.53
<b>RTM AIR COMPRESSORS -- TANK MOUNTED</b>			
RASCO AIR,RTM25033-80100,1/3HP,115/220VA	6872000023	13RTM	S\$ 7,875.35
RASCO AIR,RTM36575-80100,3/4HP,115/220VA	6872000024	34RTM	S\$10,080.45
RASCO AIR,RTM550100-80100,1HP,115/220VAC	6872000025	1RTM	S\$12,600.56
RASCO AIR,RTM915150-80100,1-1/2HP 115/22	6872000026	112RTM	S\$16,065.71
RASCO AIR,RTM1100200-80100 2HP,115/220VA	6872000027	2RTM	S\$18,585.82
<b>CONNECTION KITS</b>			
Connection Kit, Tankless Compressor	650120011G	CKTL	S\$ 773.36
Connection Kit, Tank Mounted Compressor	650120011H	CKTM	S\$ 1,863.31
<b>FLEX HOSE -- SOLD SEPARATELY</b>			
Flex Hose, Stainless Steel, 1/2" x 30"	6872000000	QRMFLEX	S\$ 286.66

Items shown on this sheet may not be stocked at all Reliable warehouses. Please contact your local Reliable Warehouse for Availability. Refer to technical data sheets for specific listings, approvals and design parameters.